

Twist-Lock® Devices

50A, 3 Phase 250V AC, 3 Pole, 4 Wire Grounding

Insulgrip® Connector with conduit adapter



Features

- Capable of accepting metallic or non metallic conduit fittings
- Box terminal with hex socket threaded slug, permits high clamping pressure on conductors without damaging strands
- Thermoplastic polyester interior provides heat resistance and impact strength
- Oversized contacts minimize operating temperature



Ordering Information


| Description                         | NPT Size | UPC Number  | Catalog Number |
|-------------------------------------|----------|-------------|----------------|
| Nylon cover, thermoplastic interior | 1"       | 78358558047 | CS8364CA10     |

Listings

Listed to UL 498  
Certified to CSA C22.2 No.42

Specifications

|                   |                         |
|-------------------|-------------------------|
| Housing           | Nylon                   |
| Terminal Retainer | Thermoplastic polyester |
| Contacts          | Brass                   |
| Terminal Screws   | Stainless Steel         |

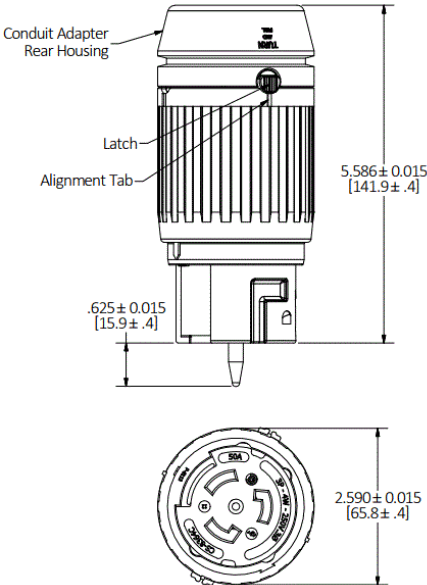

Performance

| Electrical             |  |
|------------------------|--|
| Current Interrupting   | Certified for current interrupting at full rated current |
| Dielectric voltage     | 2,000V minimum   |
| Environmental          |  |
| Flammability           | HB or better   |
| Operating Temperatures | Maximum Continuous 75C Minimum -40C (w/o impact)         |
| Mechanical             |  |
| Terminal Accommodation | #8 - #4 AWG stranded copper wire only                    |

Complementary Products

|                 |            |
|-----------------|------------|
| Conduit Fitting | H1001 (1") |
|-----------------|------------|

Online Resources

eCatalog

