

Straight Blade Devices

20A, 125V, 2 Pole, 3 Wire Grounding

Commercial Specification Grade Style Line®

Decorator Duplex Receptacles

- Features
- Weather-resistance complies with national electrical code requirements
 - Tamper-resistant shutter complies with national electrical code requirements
 - Aesthetic Style Line® decorator design
 - Smooth face
 - Triple wipe contacts

Ordering Information

Description	Device Color	UPC Number	Catalog Number
Weather and Tamper-Resistant, Style Line® decorator	Light Almond	783585144870	DR20LAWRTR

Listings

UL Listed to UL498 File No. E2186
Certified to CSA, C22.2, No. 42
NEMA® WD-6 Compliant

Specifications

Face	Nylon
Base	Nylon
Power Contacts	.030 in. (.8) Brass
Wire Clamp	.062 in. (1.6) Nickel plated steel
Mounting Strap Material	.040" (1) Galvanized steel
Terminal Screws	Stainless steel
Automatic Self-grounding Staple	Stainless steel
Mounting Screws	Stainless steel


Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Product Identification	Ratings are a permanent part of the device
Terminal Accommodation	#12-#10 AWG copper stranded or solid conductor only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA
Environmental	
Flammability	UL 94 V-2
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)

HUBBELL



20A 125V
NEMA 5-20R
UL CSA
1 HP

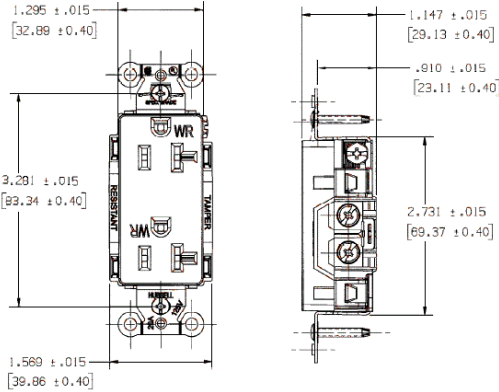

Complementary Products

Wallplate or Weatherproof Cover	StyleLine® Decorator Opening
---------------------------------	------------------------------

Online Resources

Customer Sales Drawings
eCatalog
Installation Instructions

