

Ground Fault Products  
Extra Heavy Duty Industrial & Hospital Grade  
GFCI Receptacles  
Tamper-Resistant and Weather Resistant

HUBBELL

Features

- 10kA Short Circuit Current Rating
- Limits improper access to energized contacts
- Power indication
- Ground fault indicator
- No power at face if reverse wired

Ordering Information


| Description   | Color | UPC          | Catalog Number |
|---|-------|--------------|----------------|
| 20A, 125V, Style Line®, hospital grade AUTOGUARD® self test GFCI receptacle, tamper-resistant and weather resistant, flush face, back and side wired, multiple drive screws | Black | 783585441177 | GFR8300SGBK    |

Listings

UL Listed - Canadian and U.S.  
Meets ADA Standards  
Meets all NEC® requirements  
CSA Certified  
Fed Spec  
NEMA® WD-6 Compliant

Specifications

|                 |                   |
|-----------------|-------------------|
| Face            | PBT               |
| Base            | PBT               |
| Power Contacts  | Brass             |
| Ground Contacts | Brass             |
| Mounting Strap  | Brass             |
| Mounting Screws | Zinc plated steel |

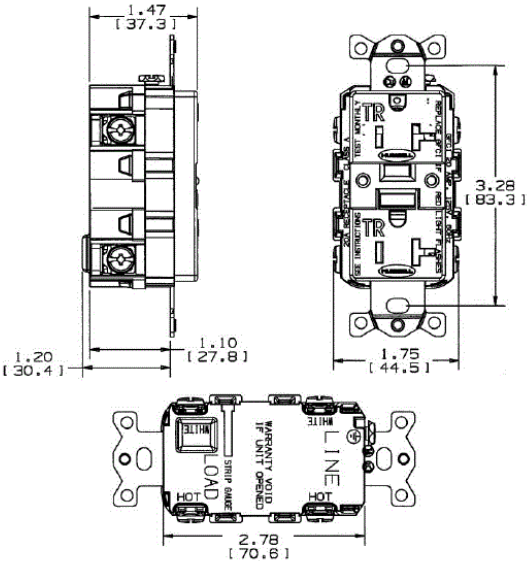

Online Resources

Customer Use Drawing  
eCatalog  
Installation Instructions

