

Switches, Double Pole, Double Throw
20A, 120-277V AC
HBL® Extra Heavy Duty Industrial Switch

Features

- Large brass binding head screws with deep slots
- Abuse resistant nylon toggle
- Strip gauge for accurate wiring

Ordering Information

Description	Toggle Color	UPC	Catalog Number
Three Position, Two Circuit, Center Off, Double Pole, Double Throw	White	783585432694	HBL1386W

Listings

Fed. Spec. W-S-896
UL Listed
CSA Certified

Specifications

Top Material	Thermoset
Base Material	Thermoset, Green
Toggle Material	Nylon
Contacts	Silver Alloy
Terminal Screws	Brass
Ground Screw	Brass (Green)

Performance

Electrical

Dielectric Voltage	Withstands 1500V AC minimum for 1 minute
Max. Continuous Current	20A
Max. Working Voltage	277V AC
Overload	Minimum 4.8 times rated current for 100 cycles
Temperature Rise	30°C maximum at rated current


Mechanical

Terminal Accommodations	#14 AWG min. - #10 AWG max. Solid and stranded copper wire only
-------------------------	---

Environmental

Flammability	UL 94V-2
Operating Temperature	Max. continuous: 75°C; Min. continuous: -40°C without impact

HUBBELL

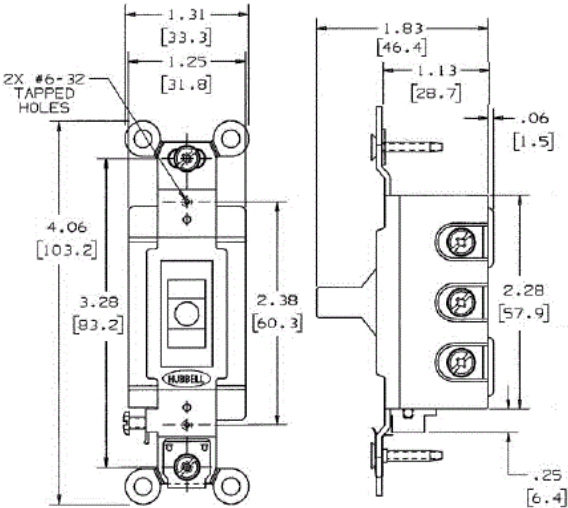

Complementary Products

Nylon Wall Plate	NP1
------------------	-----

Online Resources

Customer Use Drawing
eCatalog
Installation Instructions

