

Switches, Single Pole, Double Throw

15A, 120-277V AC

HBL® Extra Heavy Duty Industrial Switch



Features

- Large brass binding head screws with deep slots
- Requires key to actuate the switch
- Strip gauge for accurate wiring

Ordering Information

Description	Toggle Color	UPC Number	Catalog Number
Momentary Contact, Key guide, Two Circuit, Center Off, Back and Side Wired, Locking	Gray	783585188690	HBL1556LG

Listings


UL Listed
CSA Certified
Fed. Spec. W-S-896

Specifications

Top Material	Thermoplastic
Base Material	Thermoset, Blue
Key Guide	Metallic, Gray
Contacts	Silver Alloy
Terminal Screws	Brass
Ground Screw	Brass (Green)

Performance

Electrical	
Dielectric Voltage	Withstands 1500V AC minimum for 1 minute
Max. Continuous Current	15A
Max. Working Voltage	277V AC
Overload	Minimum 4.8 times rated current for 100 cycles
Temperature Rise	30°C maximum at rated current
Mechanical	
Terminal Accommodations	#14 AWG min. - #10 AWG max. Solid and stranded copper wire only
Environmental	
Flammability	UL 94V-2
Operating Temperature	Max. continuous: 75°C; Min. continuous: -40°C without impact

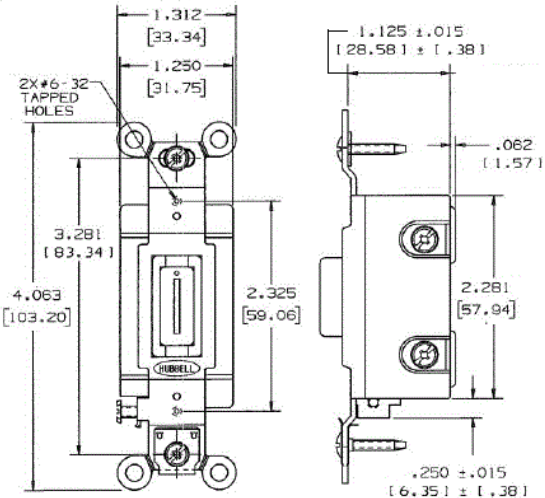

Complementary Products

Nylon Wall Plate	NP1GY
Stainless Steel Wall Plate	SS1
Replacement Key	HBL1209

Online Resources

Customer Use Drawing
eCatalog
Installation Instructions

