

Twist-Lock® Devices
20A, 125V AC, 2 Pole, 3 Wire Grounding
Corrosion Resistant Valise® Plug

HUBBELL

Features

- Powerful cord grip prevents conductor slippage and strain on wiring terminals
- Totally insulated impact and crush resistant nylon body
- Unique patented corrosion resistant clamp type terminals provide a superior electrical connection by bundling the conductor strands when clamps are tightened

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Corrosian resistant, yellow nylon.	.325"-.720" (8.26-18.3)	783585808161	HBL23CM11V

Listings


Listed to UL 498
Fed.Spec. W-C-596
Certified to CSA C22.2 No.42

Specifications

Blades	Brass - Nickel plated
Terminal Clamps	Silicon Bronze - Nickel plated
Terminal Screws	#8 - 32 Stainless Steel (Philips / Slotted / Robertson)
Housing	Yellow nylon
Clamp Screws	#8 - 32 Stainless Steel - (Philips / Slotted / Robertson)

Performance

Electrical	
Current Interrupting	Certified for full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Terminal Accommodation	#18 AWG - #10 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
Environmental	
Flammability	HB or better per UL 94 or CSA 22.2 No. 0.6
Moisture Resistance	IP20 Suitability
Operating Temperatures	Maximum Continuous 75°C Minimum -40°C (w/o impact)

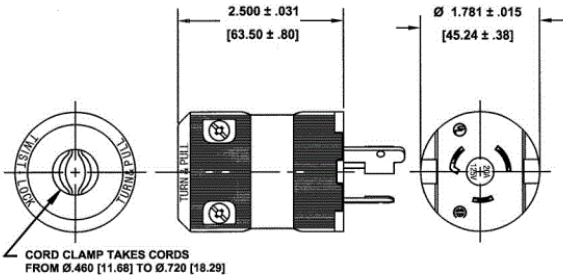

Accessories

Connector	HBL23CM13V
Single Receptacle	HBL23CM10
Flanged Receptacle	HBL2316
Weatherproof Boot	HBL60CM31V

Resources

Customer Use Drawing
eCatalog

