

Metal Raceway
2400 Series
Base & Cover



Features

- Rated for upto 600V AC
- Base, Base & Cover, and Cover only options
- Full line of fittings and accessories in the same color
- UL Listed

Ordering Information


| Series | Color | UPC Number |
|----------|-------|--------------|
| HBL 2400 | Ivory | 783585341415 |

Listings

UL Standard UL 5
 CSA Standard C22.2 no. 62
 E253976 / E253830 / E253833

Specifications

| | |
|------------------|--------|
| Color/Finish | Ivory |
| Material | Steel |
| Length per Piece | 5' |
| NEMA Type | NEMA 1 |
| Channel Type | Single |

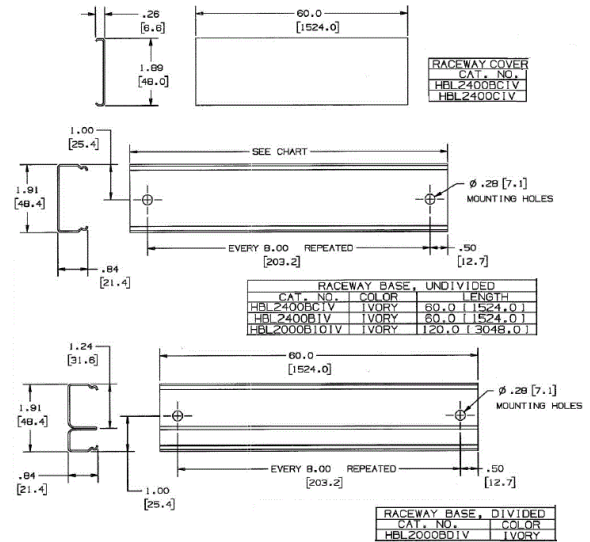

Related Products

| | |
|-------------------------|------------|
| 1 Gang Box | HBL2448IVA |
| Blank End Fitting | HBL2410BIV |
| Cover Clip | HBL2406IV |
| Flat Elbow Bend Radius | HBL2411IV |
| Tee Fitting Bend Radius | HBL2415IV |

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

