

Twist-Lock® Devices
30A, 2 Pole, 3 Wire, 240VAC, Line to Neutral

Insulgrip® Plug

Features

- Ribbed nylon housing provides a secure grip and impact and chemical resistance.
- Superior cord grip design protects terminations from excess strain.
- Clear, funnel shaped wire entry for ease of termination.
- Integral, dust shield protects wiring chamber from dust or contaminants.

Ordering Information

| Description | Cord Diameter | UPC Number | Catalog Number |
|-----------------------|---------------|--------------|----------------|
| Black and White Nylon | .360"- .930" | 783585580289 | HBL2601 |

Listings

Listed to UL 498
Fed.Spec. W-C-596
Certified to CSA C22.2 No.42

Specifications

| | |
|--------------------|-----------------------|
| Housing/Cord Clamp | Nylon |
| Terminal Retainer | Clear Polycarbonate |
| Blades | Brass |
| Terminal Screws | #10-32 Brass |
| Assembly Screws | Steel – nickel plated |

Performance

Electrical

| | |
|----------------------|---------------------------------|
| Current Interrupting | Certified at full rated current |
| Dielectric voltage | 2,000V minimum |


Mechanical

| | |
|-------------------------|---|
| Terminal Accommodation | #16 - #8 AWG stranded |
| Terminal Identification | Terminals identified in accordance with UL498 |

Environmental

| | |
|------------------------|--|
| Flammability | HB or better per UL94/CSA 22.2 No.0.17 |
| Moisture Resistance | IP20 Suitability |
| Operating Temperatures | Maximum Continuous 75C Minimum -40C (w/o impact) |

HUBBELL

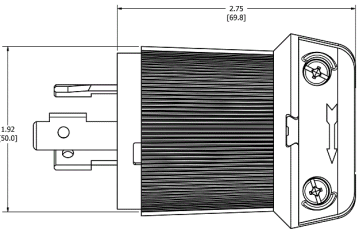

Complementary Products

| | |
|-------------------|---------|
| Connector | HBL2603 |
| Weatherproof Boot | HBL6031 |
| Receptacle | HBL2600 |

Online Resources

eCatalog

