

**Twist-Lock® Devices**  
**30A, 2 Pole, 3 Wire, 240VAC, Line to Neutral**

# HUBBELL

## Insulgrip® Connector

### Features

- Ribbed nylon housing provides a secure grip and impact and chemical resistance.
- Superior cord grip design protects terminations from excess strain.
- Clear, funnel shaped wire entry for ease of termination.
- Integral, dust shield protects wiring chamber from dust or contaminants.



**30A 240V AC**  
**NEMA L25-30R**  
**UL/CSA**



### Ordering Information


| Description           | Cord Diameter | UPC Number   | Catalog Number |
|-----------------------|---------------|--------------|----------------|
| Black and White Nylon | .360" - .930" | 783585580296 | <b>HBL2603</b> |

### Listings

Listed to UL 498  
 Fed.Spec. W-C-596  
 Certified to CSA C22.2 No.42

### Specifications

|                    |                       |
|--------------------|-----------------------|
| Housing/Cord Clamp | Nylon                 |
| Terminal Retainer  | Clear Polycarbonate   |
| Contacts           | Brass                 |
| Terminal Screws    | #10-32 Brass          |
| Assembly Screws    | Steel – nickel plated |

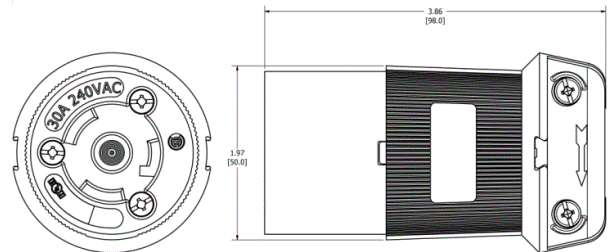

### Performance

#### Electrical

|                      |                                 |
|----------------------|---------------------------------|
| Current Interrupting | Certified at full rated current |
| Dielectric voltage   | 2,000V minimum                  |

#### Mechanical

|                         |   |
|-------------------------|---|
| Terminal Accommodation  | #16 - #8 AWG stranded                         |
| Terminal Identification | Terminals identified in accordance with UL498 |

#### Environmental

|                        |  |
|------------------------|--|
| Flammability           | HB or better per UL94/CSA 22.2 No.0.17           |
| Moisture Resistance    | IP20 Suitability                                 |
| Operating Temperatures | Maximum Continuous 75C Minimum -40C (w/o impact) |

### Complementary Products

|                   |         |
|-------------------|---------|
| Plug              | HBL2601 |
| Inlet             | HBL2605 |
| Weatherproof Boot | HBL6032 |

### Online Resources

eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

