

Twist-Lock® Devices
 30A, 125V AC, 2 Pole, 3 Wire Grounding
 Valise® Plug

HUBBELL

Features

- Powerful cord grip prevents conductor slippage and strain on wiring terminals
- Totally insulated impact and crush resistant nylon body
- Unique patented clamp type terminals provide a superior electrical connection by bundling the conductor strands when clamps are tightened

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Yellow nylon.	.590"-.930" (15.0-23.6)	783585235967	HBL2611VY

Listings

Listed to UL 498
 Fed.Spec. W-C-596
 Certified to CSA C22.2 No.42

Specifications

Housing	Yellow nylon
Blades	Brass
Terminal Screws	#8 - 32 Steel (Philips / Slotted / Robertson)
Terminal Clamps	Steel - Nickel plated
Clamp Screws	#8 - 32 Steel - Zinc plated (Philips / Slotted / Robertson)

Performance

Electrical

Current Interrupting	Certified for full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical

Terminal Accommodation	#14 AWG - #8 AWG stranded copper wire only.
------------------------	---


Terminal Identification	Terminals identified in accordance with UL 498
-------------------------	--

Environmental

Flammability	HB or better per UL 94 or CSA 22.2 No. 0.6
Moisture Resistance	IP20 Suitability
Operating Temperature	Maximum continuous 75°C, minimum -40°C (w/o impact)



30A 125V
 NEMA L5-30P
 UL/CSA
 2 HP

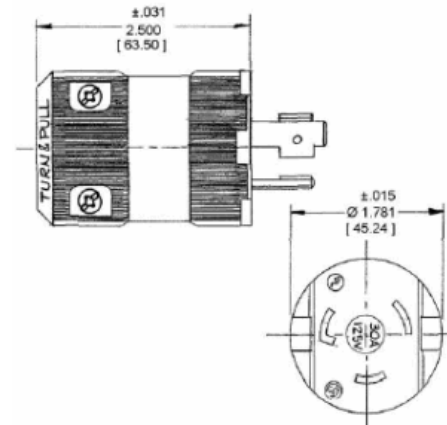

Accessories

Connector	HBL2613VY
Single Receptacle	HBL2610
Flanged Receptacle	HBL2616
Weatherproof Boot	HBL60CM31V

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

