

Twist-Lock® Devices  
 30A, 3 Phase Y 277/480V AC, 4 Pole, 5 Wire  
 Grounding  
 Insulgrip® Plug

# HUBBELL



30A 3ØV  
 277/480V AC  
 NEMA L22-30P  
 UL/CSA  
 10 HP



## Features

- Ribbed nylon housing provides a secure grip and impact and chemical resistance.
- Superior cord grip design protects terminations from excess strain.
- Clear, funnel shaped wire entry for ease of termination.
- Integral dust shield protects wiring chamber from dust or contaminants.

## Ordering Information

| Description            | Cord Diameter       | UPC          | Catalog Number |
|------------------------|---------------------|--------------|----------------|
| Black and white nylon. | .350"-1.150" (9-29) | 783585039695 | HBL2821        |

## Listings

Listed to UL 498  
 Fed.Spec. W-C-596  
 Certified to CSA C22.2 No.42

## Specifications

|                      |   |
|----------------------|---|
| Housing / Cord Clamp | Nylon   |
| Terminal Retainer    | Clear polycarbonate                           |
| Blades               | Brass   |
| Terminal Screws      | #10-32 Brass (Phillips / Slotted / Robertson) |
| Terminal Clamp       | Cold rolled steel – nickel plated             |
| Assembly Screws      | Steel - nickel plated                         |

## Performance

### Electrical

Current Interrupting Certified for current interrupting at full rated current  
 Dielectric Voltage 2,000V minimum


### Mechanical

Terminal Accommodation #16 AWG - #8 AWG stranded copper wire only.

Terminal Identification Terminals identified in accordance with UL 498

### Environmental

Flammability HB or better per UL94/CSA 22.2 No.0.17  
 Moisture Resistance IP20 Suitability  
 Operating Temperatures Maximum Continuous 75°C Minimum -40°C (w/o impact)

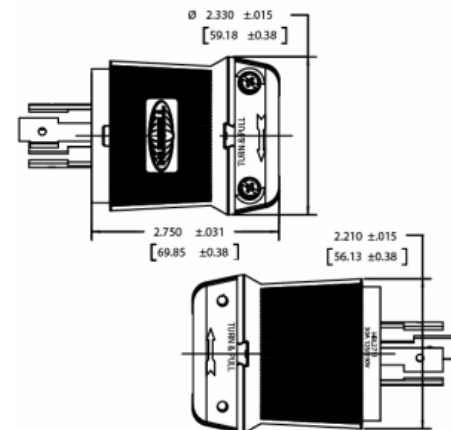

## Accessories

|                    |         |
|--------------------|---------|
| Connector          | HBL2823 |
| Single Receptacle  | HBL2820 |
| Flanged Receptacle | HBL2826 |
| Weatherproof Boot  | HBL6035 |

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

