

Twist-Lock® Devices Mechanical Interlock Replacement Part Replacement Ground Block


HUBBELL

Ordering Information

Description	Product Type	UPC	Catalog Number
Mechanical Interlock Replacement Part	Replacement Ground Block	783585955148	HBL30RGB

Listings

Listed to UL Standard
CSA Certified TYPE 4, 4X and TYPE 12K Enclosure Rating

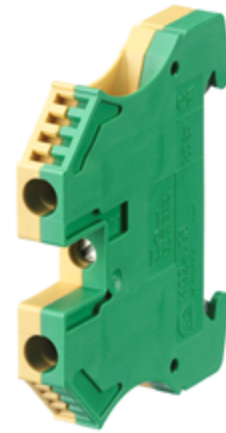

Accessories

Enclosure Accommodation	Hubbell 30A Non-Fused Switched Enclosure and Non-Fused Mechanical Interlocks with Interior Switches
-------------------------	---

Performance

Electrical

Current Interrupting Certified for current interrupting at full rated current voltage

Dielectric Voltage Withstands 3,000V Min
Electrical Operations

Mechanical

Product Identification Identification and ratings are part of the external label and receptacle face

Terminal Identification In accordance with UL, CSA

Environmental

Flammability Meets UL 94V0 material classification

Moisture Resistance IP66 suitability

Operating Temperature Maximum continuous +75°C; Minimum continuous -40°C

UV Resistance All exposed materials are UV stabilized

Resources

[eCatalog](#)

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

