

Straight Blade Devices  
15A, 125V, 2 Pole, 3 Wire Grounding  
4-PLEX® Hospital Grade Receptacle

HUBBELL

Features

- Anchor hole and loop feature secures solid wire for fast, easy terminations
- Triple wipe contacts
- Easily accessible break-off tabs for split wiring
- Three conductors energize all four outlets

Ordering Information

| Description                       | Device Color | UPC          | Catalog Number |
|-----------------------------------|--------------|--------------|----------------|
| Hospital grade, 4-PLEX receptacle | Red          | 783585016122 | HBL415HR       |

Listings

UL Listed to UL498 File No. E2186  
Certified to CSA, C22.2, No. 42 File 285  
NEMA® WD-6 Compliant

Specifications


|                 |                            |
|-----------------|----------------------------|
| Face            | Polycarbonate              |
| Base            | PBT                        |
| Power Contacts  | .032 in. (.8) Brass        |
| Ground Contacts | .031 in. (.8) Brass        |
| Ground Plate    | .032 in. (.8) Plated Steel |

Performance

|                      |                                                           |
|----------------------|-----------------------------------------------------------|
| <b>Electrical</b>    |                                                           |
| Current Interrupting | Capable of withstanding a fault level of 1000A, per UL498 |
| Dielectric Voltage   | Withstands 2,000V minimum                                 |

|                         |                                                        |
|-------------------------|--------------------------------------------------------|
| <b>Mechanical</b>       |                                                        |
| Product Identification  | Ratings are a permanent part of the device             |
| Terminal Accommodation  | #14-#12 AWG copper stranded or solid conductor only    |
| Terminal Identification | Terminals identified in accordance with UL 498 and CSA |

|                        |                                                     |
|------------------------|-----------------------------------------------------|
| <b>Environmental</b>   |                                                     |
| Flammability           | UL 94V-2                                            |
| Operating Temperatures | Maximum continuous 75°C; minimum -40°C (w/o impact) |

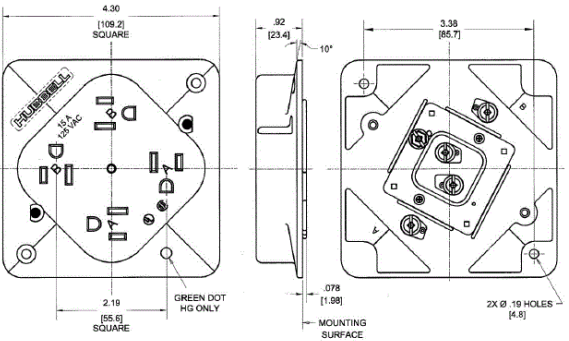

Accessories

|                      |         |
|----------------------|---------|
| 4-PLEX Adapter Plate | HBL4APR |
|----------------------|---------|

Resources

|                      |
|----------------------|
| Customer Use Drawing |
| eCatalog             |

