

Non-NEMA Twist-Lock® Devices
30A, 250V DC Max. and 600V AC Max. 50- 400
Hz 4 Pole, 5 Wire Grounding
Variload® Plug

Features

- Heat resistant thermoset construction
- Non-interchangeable center pin configuration to be designated to different circuits

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
4P5W, 30A 600V AC Max, Non-NEMA, Black Nonmetallic Body	.625"-1.00" (15.9-25.4)	783585236513	HBL45115

Listings

Listed to UL 498
Certified to CSA C22.2 No.42


Specifications

Housing	Molded Thermoset
Cover	Molded thermoset
Cord Clamp	Zinc Plated Steel
Blades	Brass
Terminal Screw	Brass
Assembly Screws	Brass

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Terminal Accommodation	#14 AWG - #10 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
Environmental	
Flammability	HB or better per UL 94 or CSA 22.2 No. 0.6
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

HUBBELL

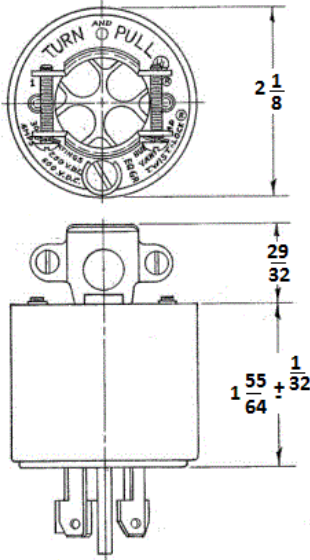

Accessories

Connector	HBL45135
Single Receptacle	HBL45105
Weatherproof Boot	HBL6027

Resources

Customer Use Drawing
eCatalog

