

Non-NEMA Twist-Lock® Devices  
 30A, 250V DC Max. and 600V AC Max. 50- 400  
 Hz 4 Pole, 5 Wire Grounding

## Variload® Plug

### Features

- Heat resistant thermoset construction
- Non-interchangeable center pin configuration to be designated to different circuits

### Ordering Information

Description	Cord Diameter	UPC	Catalog Number
4P5W, 30A 600V AC Max, Non-NEMA, Black Nonmetallic Body	.625"-1.00" (15.9-25.4)	783585236575	HBL45315

### Listings

Listed to UL 498  
 Certified to CSA C22.2 No.42


### Specifications

Housing	Molded Thermoset
Cover	Molded thermoset
Cord Clamp	Zinc Plated Steel
Blades	Brass
Terminal Screw	Brass
Assembly Screws	Brass

### Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Terminal Accommodation	#14 AWG - #10 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
Environmental	
Flammability	HB or better per UL 94 or CSA 22.2 No. 0.6
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

# HUBBELL

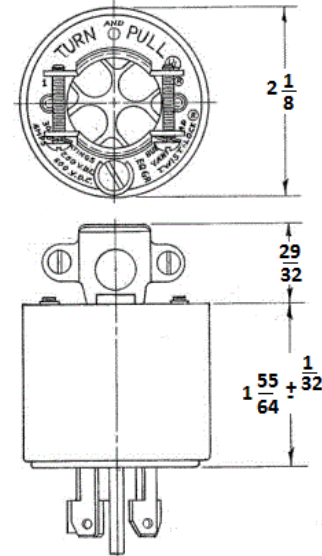

### Accessories

Connector	HBL45335
Single Receptacle	HBL45305
Weatherproof Boot	HBL6027

### Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

