

Twist-Lock® Devices
15A, 250V, 2 Pole, 3 Wire Grounding
Receptacle



Features

- Reinforced thermoplastic construction
- Single piece, all brass contacts
- Single point break-off tabs
- Mounting strap tabs lock the body and base together

Ordering Information

Description	Device Color	UPC	Catalog Number
Duplex, ring terminal connection	Brown	783585318547	HBL4550RT

Listings


Listed to UL 498
Fed. Spec. W-C-596
Certified to CSA C22.2 No.42

Specifications

Face	RTP
Base	RTP
Contacts	Brass
Ground Contact	Brass
Terminal Screws	Brass

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Terminal Accommodation	#18 AWG - #10 AWG solid or stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
Environmental	
Flammability	HB or better per UL94/CSA 22.2 No.0.17
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

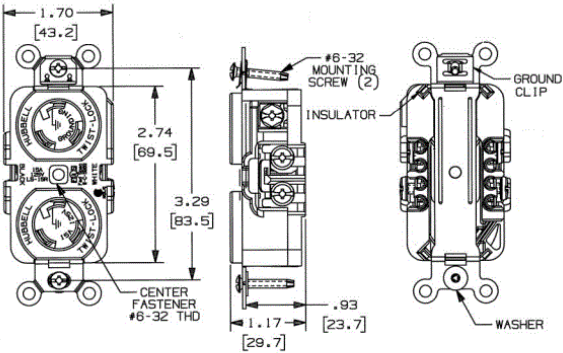

Accessories

Plug	HBL4570C
Wallplate or Weatherproof Cover	Duplex Opening

Resources

Customer Use Drawing
eCatalog

