

Twist-Lock® Devices  
 15A, 250V, 2 Pole, 3 Wire Grounding  
 Valise® Plug

# HUBBELL

## Features

- Two captive multiple drive assembly screws
- Totally insulated impact and crush resistant nylon body
- Powerful cord grips prevent conductor slippage and strain on wiring terminals



15A 250V  
 NEMA L6-15P  
 UL/CSA  
 1.5 HP



## Ordering Information


Description	Cord Diameter	UPC	Catalog Number
Yellow nylon.	.220"-.660" (5.6-16.8)	783585236650	HBL4573VY

## Listings

Listed to UL 498  
 Fed.Spec. W-C-596  
 Certified to CSA C22.2 No.42

## Specifications

Housing	Nylon
Cable Inserts	Polyphenylene Oxide
Blades	Brass
Terminal Screws	#6-32 Brass (Phillips / Slotted / Robertson)
Terminal Clamp	Cold rolled steel – nickel plated
Assembly Screws	Steel - Zinc plated

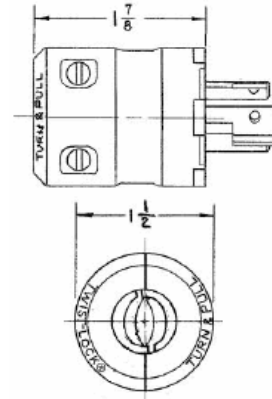

## Performance

### Electrical

Current Interrupting Certified for current interrupting at full rated current  
 Dielectric Voltage Withstands 2,000V minimum

### Mechanical

Terminal Accommodation #18 AWG - #12 AWG stranded copper wire only.

Terminal Identification Terminals identified in accordance with UL 498

### Environmental

Flammability HB or better per UL 94 or CSA 22.2 No. 0.6  
 Moisture Resistance IP20 Suitability  
 Operating Temperatures Maximum Continuous 75°C Minimum -40°C (w/o impact)

## Accessories

Connector	HBL4579VY
Duplex Receptacle	HBL4550
Single Receptacle	HBL4560
Flanged Receptacle	HBL4585C

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

