

Twist-Lock® Devices  
 15A, 250V, 2 Pole, 3 Wire Grounding  
 Stainless Steel Flanged Inlet

# HUBBELL

## Features

- Heat resistant thermoset construction
- Stainless steel casing
- #5-40 terminal screws
- Mounting screws included



15A 250V  
 NEMA L6-15P  
 UL/CSA  
 1.5 HP



## Ordering Information

Description	Device Color	UPC	Catalog Number
Stainless steel casing, brown phenolic	Brown/Stainless	783585236704	HBL4586

## Listings

Listed to UL 498  
 Fed. Spec. W-C-596  
 Certified to CSA C22.2 No.42

## Specifications

Flange	Stainless steel
Blades	Brass
Terminal Screws	Brass
Mounting Screw	Nickel plated brass

## Performance

### Electrical

Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum


### Mechanical

Terminal Accommodation	#18 AWG - #10 AWG solid or stranded copper wire only.
------------------------	---

Terminal Identification	Terminals identified in accordance with UL 498
-------------------------	--

### Environmental

Flammability	HB or better per UL94/CSA 22.2 No.0.17
Moisture Resistance	IP20 Suitability
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

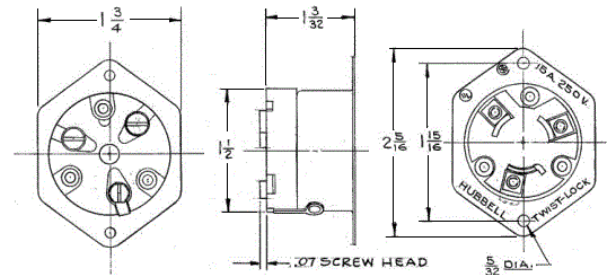

## Accessories

Connector	HBL4579C
-----------	----------

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

