

Twist-Lock® Devices  
15A, 125V, 2 Pole, 3 Wire Grounding  
Receptacle

HUBBELL

Features

- Reinforced thermoplastic construction
- Single piece, all brass contacts
- All terminals are back and side wired
- Brass mounting strap with stainless steel grounding clip

Ordering Information

Description	Device Color	UPC	Catalog Number
Single, ring terminal connection	Black	783585318578	HBL4710RT

Listings


Listed to UL 498  
Fed. Spec. W-C-596  
Certified to CSA C22.2 No.42

Specifications

Face	RTP
Base	RTP
Contacts	Brass
Clamp	Brass
Ground Contact	Brass
Terminal Screws	Brass

Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
<b>Mechanical</b>	
Terminal Accommodation	#18 AWG - #10 AWG solid or stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
<b>Environmental</b>	
Flammability	HB or better per UL94/CSA 22.2 No.0.17
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

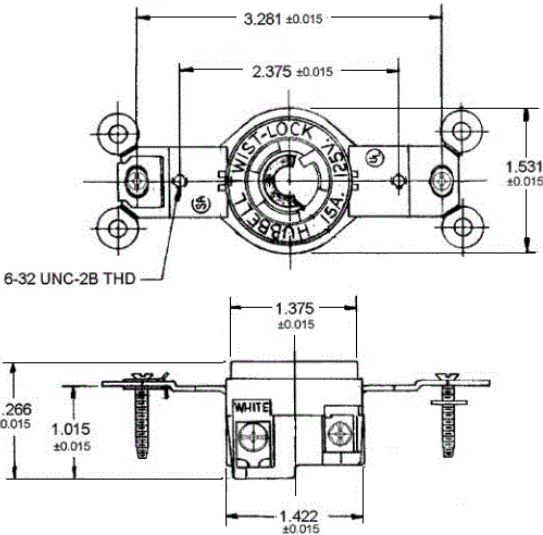

Accessories

Plug	HBL4720C
Wallplate or Weatherproof Cover	1.40" Opening

Resources

Customer Use Drawing
eCatalog

