

Straight Blade Devices

15A, 125V, 2 Pole, 3 Wire Grounding

Load:Logic® Load Control Receptacles

- Features
- Designed for Automatic Receptacle (plug load) Control
  - Half controlled face and downstream control
  - Clear Connect/Vive Enabled wireless control
  - Tamper Resistant... NOT Plug Resistant®

Ordering Information

Description	Device Color	UPC Number	Catalog Number
Decorator face, back wired	Brown	783585401904	HBL5262RFC1

Listings

cULus 498B SA UL File No. E481574  
Fed. Spec. WC596G  
Complies with:NEC Section 406.3 (E), ASHRAE 90.1 Section 8.4.2,California Title 24  
Artcile 130.5(d)  
NEMA WD-6 Compliant


Specifications

Face	Nylon
Base	Nylon
Power Contacts	0.031in (0.8) Brass
Wire Clamp	0.062in (1.6) Steel-Nickel Finish
Mounting Strap	0.047in (1.2) Brass
Terminal Screws	#8-32 Brass, Multiple Drive
Self -Grounding Staple	Stainless Steel
Mounting Screws	Zinc-Plated Steel

Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
<b>Mechanical</b>	
Product Identification	Ratings are a permanent part of the device
Terminal Accomodation	#14-10 AWG stranded or solid copper conductor only
Terminal Identification	Terminals identified in accordance with UL498 and CSA (Brass, White, Green)
<b>Environmental</b>	
Flammabilty	UL94V-2
Operating Location	Indoor Use Only
Operating Temperature	0° to 40°C (32° to 104°F) Relative Humidity (non-condensing) 0% to 95% (w/o impact)

HUBBELL

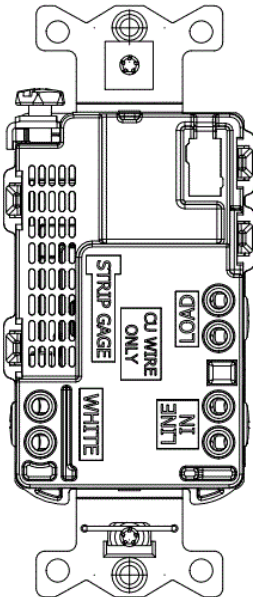

Complementary Products

Wallplate, Decorator Opening, Nylon	NP26
Wallplate, Decorator Opening, Stainless Steel	SS26

Online Resources

Customer Use Drawing  
eCatalog  
Installation Instructions

