

Straight Blade Devices  
 15A, 125V, 2 Pole, 3 Wire Grounding  
 Insulgrip Plug

# HUBBELL

## Features

- Fused plug

## Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Black vinyl housing, fusible	.296"-.625"(7.5-15.9)	783585013152	HBL5299

## Listings

CSA Certified to C22.2 No. 42 File 280

## Specifications

Housing	Vinyl
Blade Holder	Nylon
Cord Clamp	Plated Steel
Blades	.060 in. (1.5) Brass
Terminal Screws	#8-32 Brass , multiple drive
Terminal Clamp	Nickel plated steel
Assembly Screws	Nickel plated steel

## Performance

### Electrical




Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

### Mechanical

Cord Accomodation	.296"-.625"(7.5-15.9)
Terminal Identification	Terminals identified in accordance with UL 498 and CSA

### Environmental

Flammability	UL 94 HB or better
IP Suitability	IP20
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)

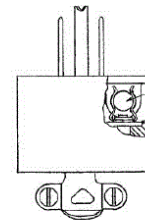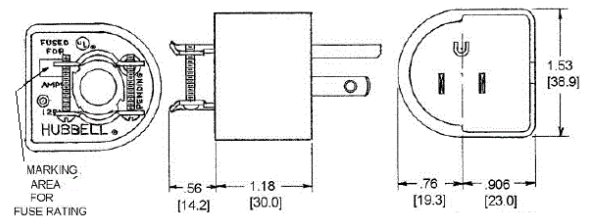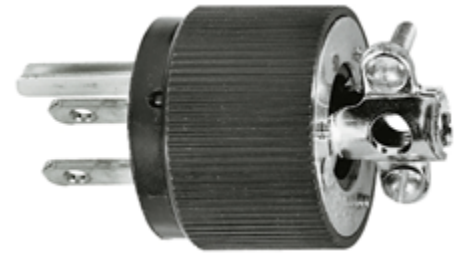

FUSE (CERAMIC TUBE FUSE - 1/4 X 1 1/4 - 15 AMP MAX. - "BUSS" TYPE ABC OR EQUIVALENT (NOT INCLUDED)) RETAINED BY AND REMOVED WITH COVER

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

