

IEC Pin and Sleeve

30A, 3 PhaseY 277/480V AC, 4 Pole, 5 Wire

Mechanical Interlock

Features

- Replaceable spring-loaded receptacle liftcover with gasket
- Plug-Check™ mechanism to detect the presence of plug

Ordering Information

Description	UPC	Catalog Number
Pin and Sleeve fused circuit-lock interlock device	783585406114	HBL530MIF7W

Color code
Red

Standards

UL Listed for US and Canada
CSA certified

Specifications

Base and Top	Valox®
Handle	Valox®
Enclosure Gasket	Neoprene
Shaft	Brass
Shaft Seal	Neoprene

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current and voltage
Dielectric Voltage	Withstands 3,000V AC Min
Max Working Voltage	600V AC

Mechanical

Impact Resistance	In accordance with UL 746C
Mounting	External adjustment feet
Terminal Identification	In accordance with UL, CSA and international conventions


Environmental

Flammability	UL94-5VA and V-0 Classification
Ingress Protection	IP66 Suitability
Operating Temperatures	Max. Continuous +75°C; Min. Continuous -40°C
UV Resistance	All materials are UV stabilized

Online Resources

Customer Use Drawing
eCatalog
Installation Instructions

HUBBELL

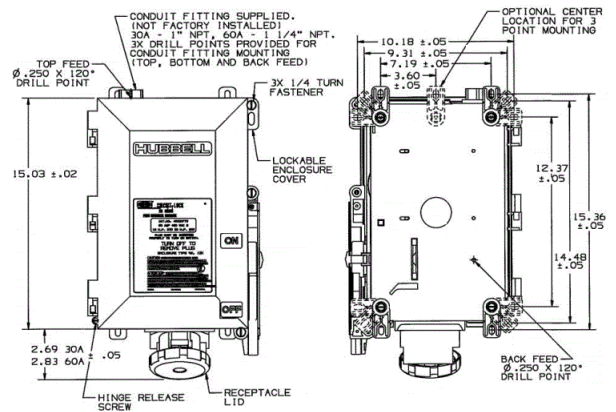

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

