

Straight Blade Devices  
15A, 250V, 2 Pole, 3 Wire Grounding  
Insulgrip® Plug

# HUBBELL

## Features

- 8-Position angled plug
- Low profile
- Roomy wiring chamber provides ample space for wiring

## Ordering Information

Description	Cord Diameter	UPC	Catalog Number
8-Position Insulgrip® Angle Plug, black and white nylon	.325"-.655"(8.3-16.6)	783585175652	HBL5666CA

## Listings

UL Listed to UL498 File E1706  
CSA Certified to C22.2 No. 42 File 280  
NEMA® WD-6 Compliant  
NEMA® WD-6 Compliant

## Specifications

Housing/Cord Clamp	Nylon
Blade Holder	Nylon
Terminal Retainer	Clear Polycarbonate
Blades	.060 in. (1.5) Brass
Terminal Screws	#8-32 Brass , multiple drive
Terminal Clamp	Nickel plated steel
Assembly Screws	Nickel plated steel

## Performance

### Electrical



Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

### Mechanical

Cord Accomodation	.325"-.655"(8.3-16.6)
Terminal Accommodation	#18-10 AWG. Standed copper wire only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA

### Environmental

Flammability	UL 94 HB or better
IP Suitability	IP20
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)

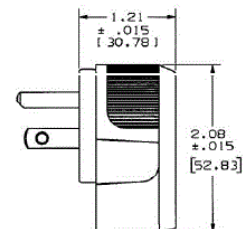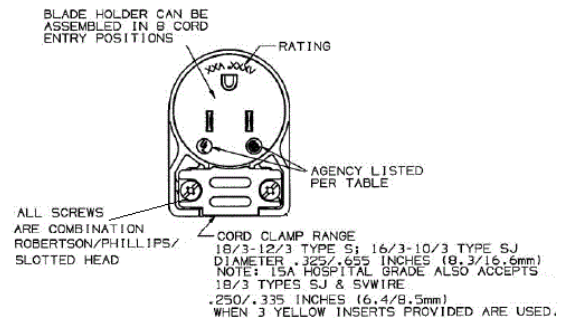

## Resources

Customer Use Drawing  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

