

Non-NEMA Twist-Lock® Devices
 20A, 125/250V AC, 3 Pole, 3 Wire
 Non-Grounding
 Single Flush Receptacle

HUBBELL

Features

- High-impact, abuse-resistant nylon face
- Wire restraint recess for both back and side wiring, greatly reduces the possibility of loosening the terminal connection
- Face color coding by voltage facilitates locating and mating of proper devices
- All-brass mounting and grounding system provides a lower resistance ground path and greater resistance to corrosion than steel mounting systems

Ordering Information

| Description | Device Color | UPC | Catalog Number |
|---------------------------------|--------------|--------------|----------------|
| Nylon face, back and side wire. | Black | 783585333625 | HBL7310B |

Listings


Listed to UL 498
 Fed.Spec. W-C-596
 Certified to CSA C22.2 No.42

Specifications

| | |
|-----------------|--|
| Face | Nylon |
| Base | Glass-Reinforced thermoplastic polyester (RTP) |
| Contacts | Brass |
| Terminal Screws | #10 - 32 Brass |
| Mounting Strap | Brass |

Performance

| | |
|-------------------------|--|
| Electrical | |
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |
| Mechanical | |
| Terminal Accommodation | #16 AWG - #8 AWG solid or stranded copper wire only. |
| Terminal Identification | Terminals identified in accordance with UL 498 |
| Environmental | |
| Flammability | V2 or better per UL94/CSA 22.2 No.0.17 |
| Moisture Resistance | IP20 Suitability |
| Operating Temperatures | Maximum Continuous 75°C; Minimum -40°C (w/o impact) |

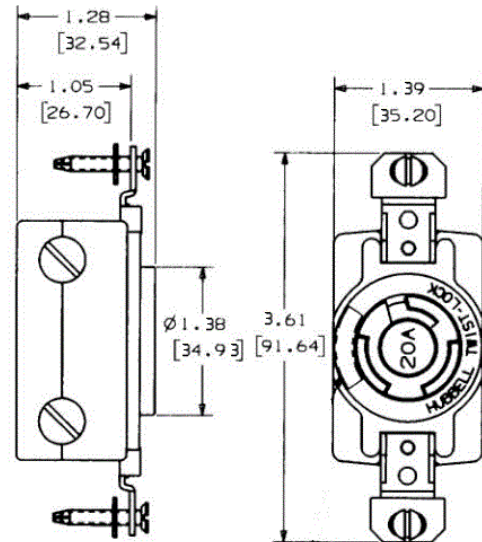

Accessories

| | |
|---------------------------------|---------------|
| Plug | HBL9965C |
| Wallplate or Weatherproof Cover | 1.60" Opening |

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

