

Twist-Lock® Devices  
 15A, 125V, 2 Pole, 2 Wire Non-Grounding  
 Insulgrip® Flanged Inlet

# HUBBELL

## Features

- Impact resistant thermoplastic construction
- Backwired terminations for ease of installation
- Mounting screws included



## Ordering Information


Description	Device Color	UPC	Catalog Number
Nylon casing, polarized, backwired.	White	783585178004	HBL7524C

## Listings

Listed to UL 498  
 Fed. Spec W-C-596  
 Certified to CSA C22.2 No. 42

## Specifications

Housing	Nylon
Terminal Retainer	Clear polycarbonate
Blades	Brass
Terminal Screws	#8-32 Brass (Phillips / Slotted / Robertson)
Terminal Clamp	Cold rolled steel – nickel plated
Assembly Screws	Steel – nickel plated
Mounting Screw	Nickel plated brass

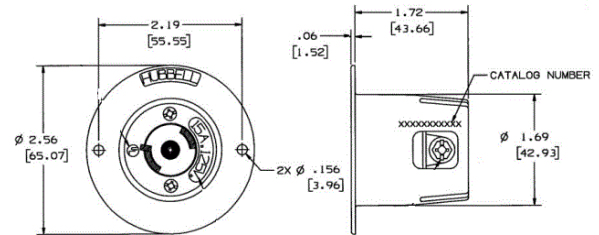

## Performance

### Electrical

Current Interrupting Certified for current interrupting at full rated current  
 Dielectric Voltage Withstands 2,000V minimum

### Mechanical

Terminal Accommodation #18 AWG - #10 AWG solid or stranded copper wire only.  
 Terminal Identification Terminals identified in accordance with UL 498

### Environmental

Flammability HB or better per UL94/CSA 22.2 No.0.17  
 Moisture Resistance IP20 Suitability  
 Operating Temperatures Maximum Continuous 75°C; Minimum -40°C (w/o impact)

## Accessories

Connector	HBL7506C
Weatherproof Lift Cover	WP1

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

