

Non-NEMA Twist-Lock® Devices  
10A, 250V/15A, 125V, 3 Pole, 3 Wire  
Non-Grounding  
Insulgrip® Connector

HUBBELL

Features

- Ribbed nylon housing provides secure, impact and chemical resistant grip
- Superior cord grip design protects terminations from excess strain
- Integral VARI-SIZE insert accommodates a wide range of cord diameters

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Yellow and white nylon.	.230"- .720" (5.8-18.3)	783585178653	HBL7565CY

Listings


Listed to UL 498  
Fed.Spec. W-C-596  
Certified to CSA C22.2 No.42

Specifications

Housing / Cord Clamp	Nylon
Terminal Retainer	Clear polycarbonate
Contacts	Brass
Terminal Screws	#8-32 Brass (Phillips / Slotted / Robertson)
Terminal Clamp	Cold rolled steel – nickel plated
Assembly Screws	Steel - nickel plated

Performance

<b>Electrical</b>	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
<b>Mechanical</b>	
Terminal Accommodation	#18 AWG - #10 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498
<b>Environmental</b>	
Flammability	HB or better per UL94/CSA 22.2 No.0.17
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

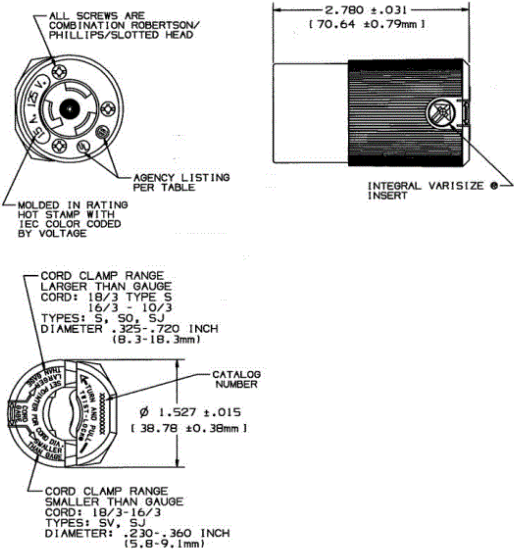

Accessories

Plug	HBL7565CY
Stainless Steel Flanged Inlet	HBL7556

Resources

Customer Use Drawing  
eCatalog

