

Twist-Lock® Devices
50A, 250V DC, 600V AC, 3 Pole, 4 Wire
Grounding
Flanged Inlet

HUBBELL

Features

- Metallic flanged casing provides maximum strength and protection
- Thermoset interior provides superior heat resistance

Ordering Information

Description	Device Style	UPC	Catalog Number
Zinc plated steel casing, thermoset interior with lift cover	Metallic	783585237879	HBL7968

Listings

Listed to UL 498
Certified to CSA C22.2 No.42

Specifications



Casing	Steel, zinc plated
Terminal Retainer	Phenolic
Blades	Brass
Terminal Screws	Steel

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical	
Terminal Accommodation	#10 AWG - #6 AWG solid or stranded copper wire only

Environmental	
Flammability	UL 94 V0
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)

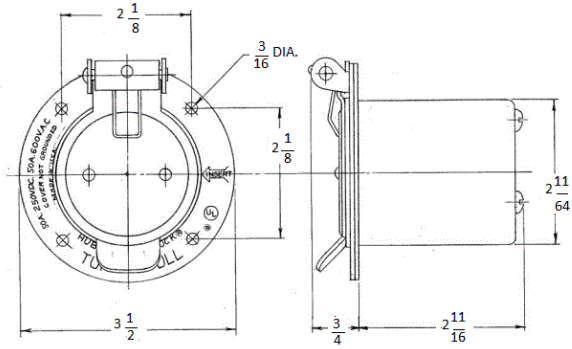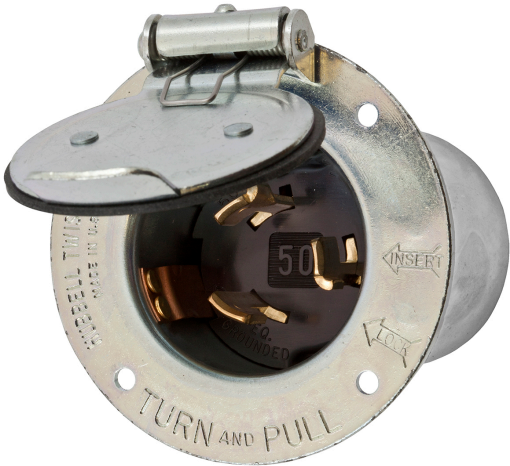

Accessories

Connector	HBL7764C
-----------	----------

Resources

Customer Use Drawing
eCatalog

