

Straight Blade Devices

20A, 125V, 2 Pole, 3 Wire Grounding

HBL[®] Extra Heavy Duty MAX Hospital Grade
Single Receptacle

Features

- One-piece nickel-plated brass integral ground strap
- Patented bypass contact design

Ordering Information

| Description | Device Color | UPC Number | Catalog Number |
|--|--------------|--------------|----------------|
| Panel mount on 1.94 in. (49.2) centers | Ivory | 783585016344 | HBL8384I |

Listings

UL Listed to UL498 File No. E2186
Certified to CSA, C22.2, No. 42 File 285
Fed. Spec. W-C-596
NEMA[®] WD-6 Compliant


Specifications

| | |
|-------------------------------|----------------------|
| Face | Nylon |
| Base | PBT |
| Power Contacts | .037 in. (.9) Brass |
| Ground Contact | Nickel plated brass |
| Clamp | Nickel plated brass |
| Mounting Strap | .050 in. (1.3) Brass |
| Automatic Self-grounding Clip | Stainless steel |
| Mounting Screws | Stainless steel |

Performance

| | |
|-------------------------|--|
| Electrical | |
| Current Interrupting | Certified for current interrupting at full rated current |
| Dielectric Voltage | Withstands 2,000V minimum |
| Mechanical | |
| Product Identification | Ratings are a permanent part of the device |
| Terminal Accommodation | #12-#10 AWG stranded or solid copper wire only |
| Terminal Identification | Terminals identified in accordance with UL 498 and CSA |
| Environmental | |
| Flammability | Top: UL 94V-2, Base: UL 94V-0 and UL 94-5 VA |
| Operating Temperatures | Maximum continuous 75°C; minimum -40°C (w/o impact) |

HUBBELL

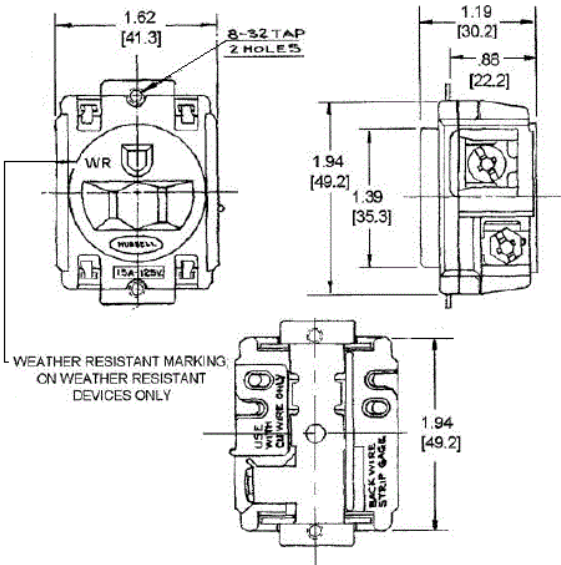

Complementary Products

| | |
|---------------------------------|---------------|
| Wallplate or Weatherproof Cover | 1.40" Opening |
|---------------------------------|---------------|

Online Resources

Customer Sales Drawings
eCatalog

