

AV In-Wall Enclosure 2-Gang AV Wall Box

HUBBELL

Features

- Ideal for delivering power, data and AV side-by-side
- Accepts industry standard wallplates for consistent appearance
- Allows for multiple options for AV in-wall solutions
- Accepts HBL989 Low Voltage Divider

Ordering Information

| Description | Surface Type | UPC | Catalog Number |
|-----------------------------|--------------|--------------|----------------|
| 4 in. deep, 2 in. knockouts | Metal | 783585459752 | HBL985 |




Listings

Listed to UL 514 A

Specifications

| | |
|-------------------|------------------|
| Volume | 54 cubic inches |
| Gangable Spacer | Galvanized Steel |
| Mounting Brackets | Galvanized Steel |
| Support Bracket | Galvanized Steel |

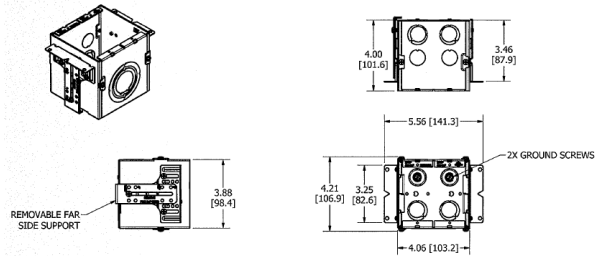

Complementary Products

Recessed TR Duplex Receptacle RR1514
with Snapfit Openings

Recessed TR Duplex Receptacle RR1512
with Cable Pass Thru

Low Voltage Partition HBL989

Online Resources

Customer Use Drawing

eCatalog

Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

