

## Features


- Spring rewind and ratchet lock
- Multi-position four roller guide and adjustable hose stop
- Full flow shafts and swivels assure maximum product delivery

## Ordering Information

| Description          | UPC Number   | Catalog Number |
|----------------------|--------------|----------------|
| Low pressure 1/4" ID | 783585243610 | HBLHR2535      |

## Specifications

|                           |             |
|---------------------------|-------------|
| Cable Length Feet (m)     | 35 (10.7)   |
| Max Pressure Psi          | 300         |
| Frame Size                | A           |
| Input Hose Fitting (NPTF) | 1/4         |
| O.D. Inch (mm)            | 0.51 (13.0) |
| Weight Lbs. (kg)          | 24 (10.9)   |

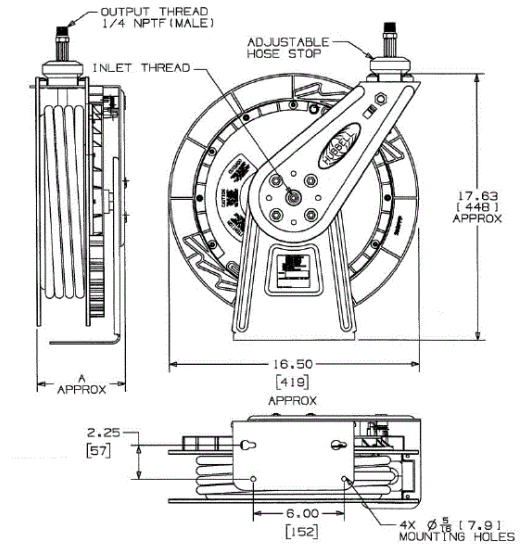

## Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions