

Features


- Spring rewind and ratchet lock
- Multi-position four roller guide and adjustable hose stop
- Full flow shafts and swivels assure maximum product delivery

Ordering Information

Description	UPC Number	Catalog Number
Low pressure 1/4" ID	783585243627	HBLHR2550

Specifications

Cable Length Feet (m)	50 (15.2)
Max Pressure Psi	300
Frame Size	B
Input Hose Fitting (NPTF)	1/4
O.D. Inch (mm)	0.51 (13.0)
Weight Lbs. (kg)	26 (11.8)

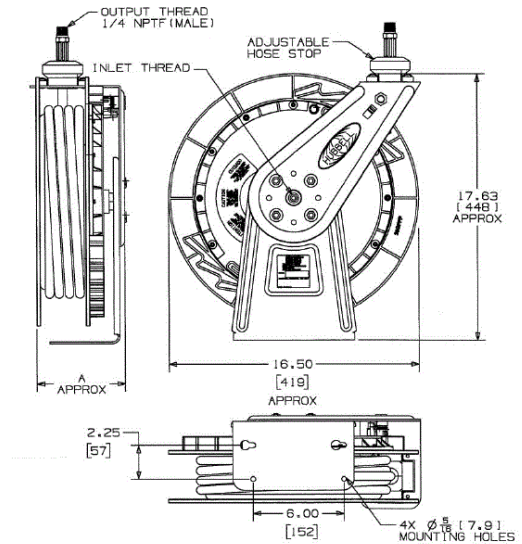

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions