

Features

- Spring rewind and ratchet lock
- Multi-position four roller guide and adjustable hose stop
- Full flow shafts and swivels assure maximum product delivery


Ordering Information

Description	UPC Number	Catalog Number
Low pressure 3/8" ID	783585243634	HBLHR3825



Specifications

Cable Length Feet (m)	25 (7.6)
Max Pressure Psi	300
Frame Size	A
Input Hose Fitting (NPTF)	3/8
O.D. Inch (mm)	0.65 (16.5)
Weight Lbs. (kg)	23 (10.4)

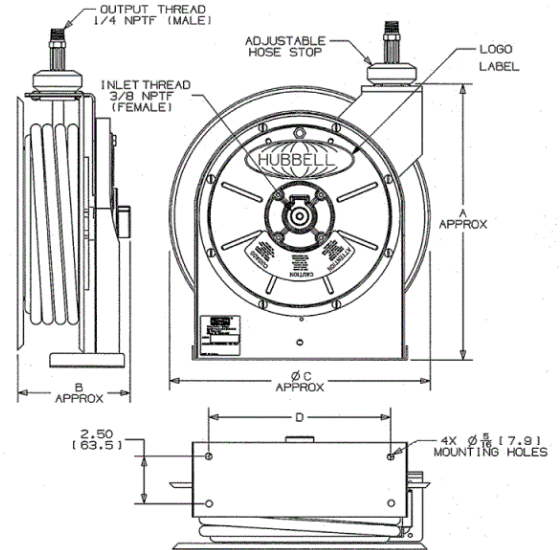

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions