

Wire Management Products

Cord and Cable Reels

Industrial Power Cord Reels



Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications

Ordering Information

Description	UPC Number	Catalog Number
Yellow Industrial Reel with HBL5369C , UL Type 1, 25 Ft , #12/3 SJO, 20 A, 125 VAC	783585585581	HBLI25123C20Y

Listings


cULus Listed

Specifications

Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum

Performance

Amperage	20 A
Max. Working Voltage	125V AC
Moisture Resistance	Dry, Indoor, Non-Hazardous Locations - UL Type 1
Number of Wires	3-Wire

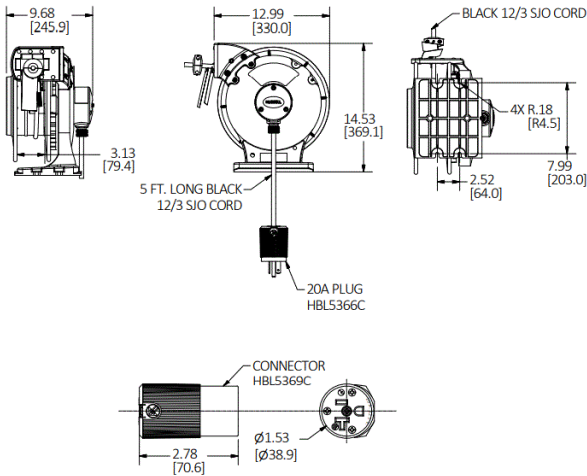

Related Products

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI12BS

Online Resources

- Customer Drawing
- Customer Sales Drawings
- eCatalog
- Installation/Instruction Manual

