

Wire Management Products

Cord and Cable Reels

Industrial Lighted Cord Reels



Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications

Ordering Information

Description	UPC Number	Catalog Number
White Industrial Reel with LED Lamp , UL Type 1, 25 Ft , #16/3 SJO, 10 A, 250 VAC	783585669618	HBLI25163LED

Listings


cULus Listed

Specifications

Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum

Performance

Amperage	10 A
Max. Working Voltage	250V AC
Moisture Resistance	Dry, Indoor, Non-Hazardous Locations - UL Type 1
Number of Wires	3-Wire

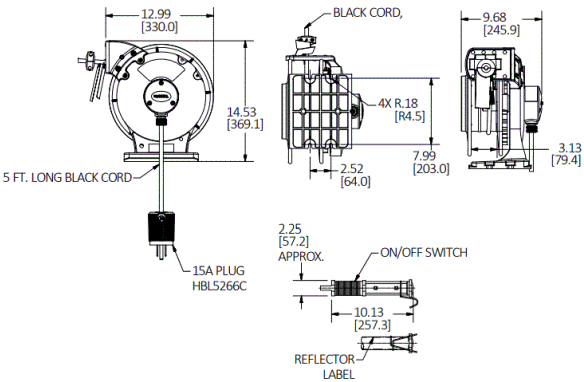

Related Products

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI16BS

Online Resources

Customer Drawing
Customer Sales Drawings
eCatalog
Installation/Instruction Manual

