

**Features**

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications



**Ordering Information**

Description	UPC Number	Catalog Number
Yellow Industrial Reel with Yellow Box, GFCI Module and (1) 20A Duplex Receptacle , UL Type 1, 35 Ft , #12/3 SJO, 20 A, 125 VAC	783585586335	HBLI35123GF20Y

**Listings**

cULus Listed

**Specifications**

Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum



**Performance**

**Amperage**  
20 A

**Max. Working Voltage**  
125V AC

**Moisture Resistance**  
Dry, Indoor, Non-Hazardous Locations - UL Type 1

**Number of Wires**  
3-Wire

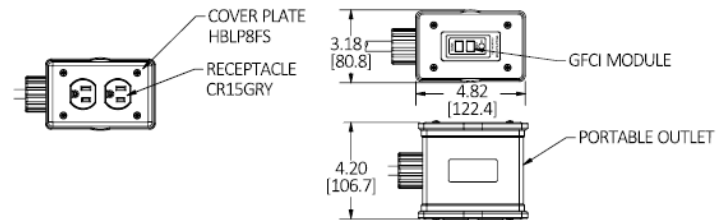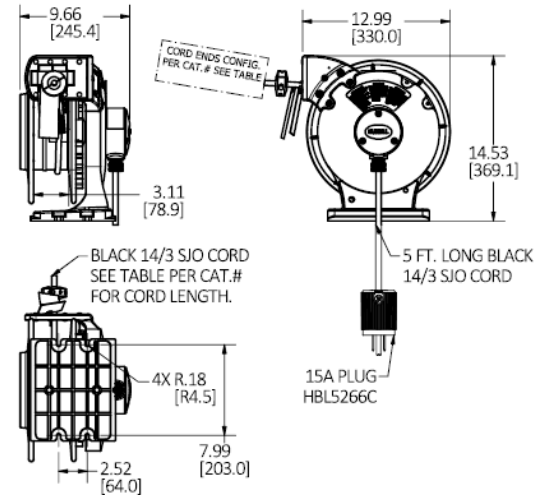

**Related Products**

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI12BS

**Online Resources**

- Customer Drawing
- Customer Sales Drawings
- eCatalog
- Installation/Instruction Manual