

Wire Management Products

Cord and Cable Reels

Industrial Power Cord Reels



Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications

Ordering Information

Description	UPC Number	Catalog Number
White Industrial Reel with Yellow Box, GFCI Module and (1) 15A Duplex Receptacle , UL Type 1, 35 Ft , #14/3 SJO, 15 A, 125 VAC	783585669410	HBLI35143GF15

Listings


cULus Listed

Specifications

Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum

Performance

Amperage	15 A
Max. Working Voltage	125V AC
Moisture Resistance	Dry, Indoor, Non-Hazardous Locations - UL Type 1
Number of Wires	3-Wire

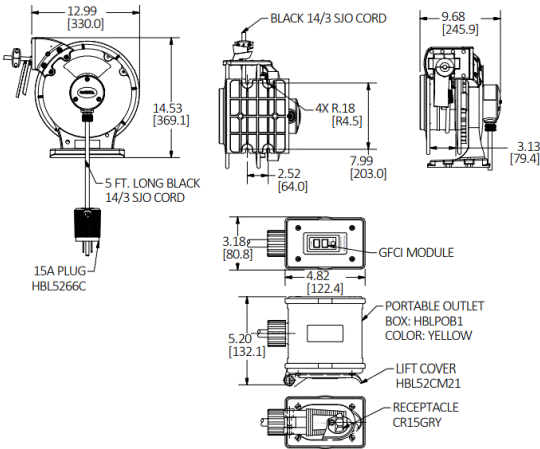

Related Products

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI16BS

Online Resources

- Customer Drawing
- Customer Sales Drawings
- eCatalog
- Installation/Instruction Manual

