

## Wire Management Products

### Cord and Cable Reels

### Industrial Power Cord Reels

#### Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Ratchet lock automatically maintains desired cord length and can be disengaged in the field for constant tension applications
- Kellems strain relief grips

#### Ordering Information

**Description**  
White Industrial Reel with Black Portable Outlet Box, GFCI Module, Kellems Strain Relief, and (2) 20A Duplex Receptacles, UL Type 1, 45 Ft, #12/3 SJO, 20 A, 125 VAC

**UPC Number** 78358570794  
**Catalog Number** HBLI45123GF220M1K

#### Listings

cULus Listed

#### Specifications

Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum

#### Performance

##### Amperage

20 A

##### Max. Working Voltage

125V AC


##### Moisture Resistance

Dry, Indoor, Non-Hazardous Locations - UL Type 1

##### Number of Wires

3-Wire

# HUBBELL

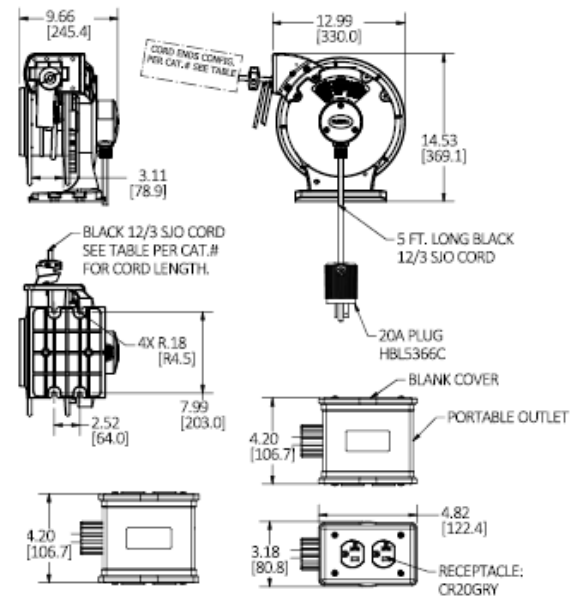

#### Related Products

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI12BS

#### Online Resources

Customer Sales Drawings  
eCatalog  
Installation/Instruction Manual

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

