

Wire Management Products

Cord and Cable Reels

Industrial Power Cord Reels



Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications

Ordering Information

Description	UPC Number	Catalog Number
Yellow Industrial Reel with Black Box, GFCI Module and (2) 20A Duplex Receptacle , UL Type 1, 45 Ft , #12/3 SJO, 20 A, 125 VAC	783585586427	HBLI45123GF220M1Y

Listings


cULus Listed

Specifications

Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum

Performance

Amperage	20 A
Max. Working Voltage	125V AC
Moisture Resistance	Dry, Indoor, Non-Hazardous Locations - UL Type 1
Number of Wires	3-Wire

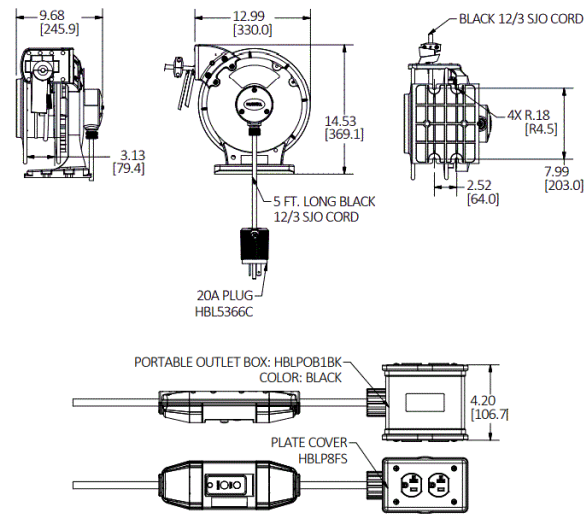

Related Products

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI12BS

Online Resources

- Customer Drawing
- Customer Sales Drawings
- eCatalog
- Installation/Instruction Manual

