

## Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications

## Ordering Information

Description	UPC Number	Catalog Number
White Industrial Reel with Black Box and (1) 15A Duplex Receptacle, UL Type 1, 45 Ft., #14/3 SJO, 15 A, 125 VAC	783585669106	HBLI45143R15M1

## Listings

cULus Listed

## Specifications

Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum

## Performance

### Amperage

15 A

### Max. Working Voltage


125V AC

### Moisture Resistance

Dry, Indoor, Non-Hazardous Locations - UL Type 1

### Number of Wires

3-Wire

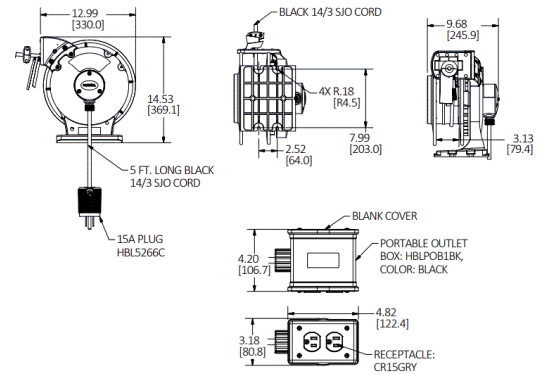

## Related Products

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI16BS

## Online Resources

Customer Drawing  
 Customer Sales Drawings  
 eCatalog  
 Installation/Instruction Manual