

Wire Management Products

Cord and Cable Reels

Industrial Lighted Cord Reels



Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications

Ordering Information

Description	UPC Number	Catalog Number
Yellow Industrial Reel with Incandescent Lamp , UL Type 1, 45 Ft , #16/3 SJO, 10 A, 250 VAC	783585669878	HBLI45163INY

Listings

cULus Listed

Specifications

Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum


Performance

Amperage  
10 A

Max. Working Voltage  
250V AC

Moisture Resistance  
Dry, Indoor, Non-Hazardous Locations - UL Type 1

Number of Wires  
3-Wire

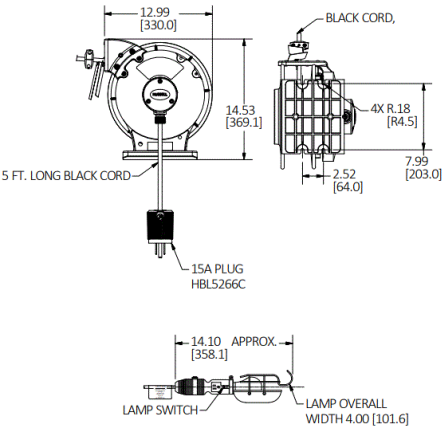

Related Products

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI16BS

Online Resources

- Customer Drawing
- Customer Sales Drawings
- eCatalog
- Installation/Instruction Manual

