

Single Pole Devices and Temporary Power

400A, 600V AC/DC

Male Receptacles



Ordering Information

Description	Device Color	UPC Number	Catalog Number
Bus Bar Mount, mates with 300 and 400A Plugs	White	783585454665	HBLMRBW

Listings


UL and cUL Listed
UL Enclosure Types 3R, 4X, 12
National Electric Code (NEC), ANSI/NFPA 70

Specifications

Base Compound	Thermoplastic Elastomer
Contact Material	Brass
Retaining Screw Material	Nylon
Mounting Hole	4x #10-32
Termination	5/16-18 UNC-2B Threaded Hole

Performance

Electrical	
Amperage Rating	400A Maximum
Voltage Rating	600V AC/DC Maximum
Mechanical	
Product Identification	Ratings are a permanent part of device
Terminal Accommodation	#4 to 4/0 AWG
Environmental	
Flammability	HB per UL94 or CSA 22.2. 0.17

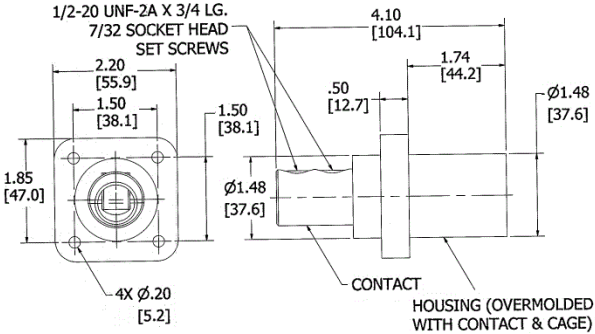

Online Resources

- Customer Sales Drawings
- eCatalog
- Installation Instructions

