

Wire Management Products

Cord and Cable Reels

Weatherproof Cord Reels



Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 4
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications

Ordering Information

| Description                                                                | UPC Number   | Catalog Number |
|----------------------------------------------------------------------------|--------------|----------------|
| White Weatherproof Reel,<br>UL Type 4, 45 Ft , #12/3<br>SOW, 20 A, 600 VAC | 783585585970 | HBLW45123W     |

Listings

cULus Listed

Specifications

|                    |               |
|--------------------|---------------|
| Spool              | Aluminum      |
| Guide Frame        | Thermoplastic |
| Cord               | Copper        |
| Internal Terminals | Copper Alloy  |
| Ball Stopper       | Thermoplastic |
| Fitting            | Aluminum      |


Performance

Amperage  
20 A

Max. Working Voltage  
600V AC

Moisture Resistance  
Dry, Indoor and Wet and Damp Outdoor, Non-Hazardous Locations - UL Type 4

Number of Wires  
3-Wire

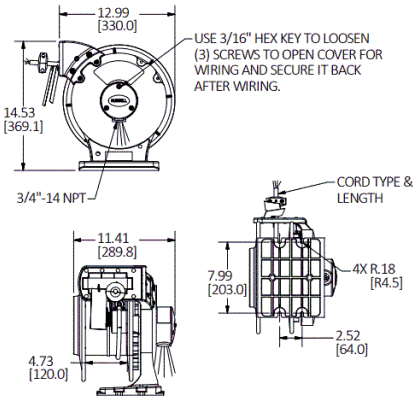

Related Products

|                  |           |
|------------------|-----------|
| Pivot Base       | HBLI340PB |
| Mounting Bracket | HBLIMB    |
| Ball Stop        | HBLI14BS  |

Online Resources

Customer Drawing  
Customer Sales Drawings  
eCatalog  
Installation/Instruction Manual

