

Xcelerator
Jacks
Xcelerator USOC Jack

- Features
- RJ-25 USOC (RJ-25) Jack
 - Exclusive 1-Punch Termination Reduces Termination Time by 75%
 - Mating Cycles Exceed Industry Standard by Four Times
 - Bulk Packaging Reduces Excess Waste on the Job

Ordering Information

Description	Color	UPC Number	Catalog No.
Xcelerator USOC Jack	Orange	662620824734	HXJUOR

- Listings
- 6-Position USOC Compliant
Mechanical TIA-568-C.2
UL Listed 1863
CSA Certified
RoHS Compliant

Specifications



Nose Contact	Beryllium copper with precious metal plating over nickel under plating
IDC Contact	Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating
Housing	High impact thermoplastic (UL 94 V-0)

Performance

Electrical	6-Position USOC Compliant
Mechanical	Contact performance confirmed over the full range of ISO/FCC compliant plug IDC Contact Termination: 10x Keystone Latching Force: 25 lbs. Nose Contact Mating Cycles: 2000

Applications

Phone
DSL

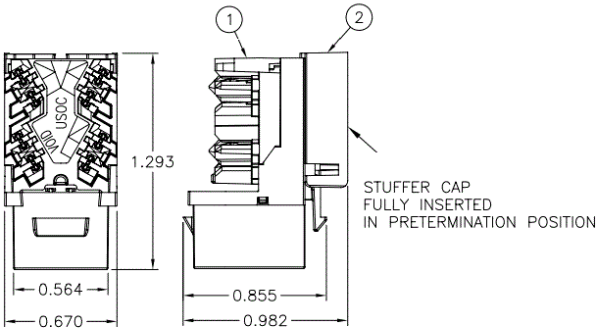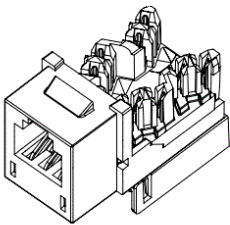

Complementary Products

1-Punch Tool	TX4P
Dust Cover	HXJDC25
Termination Puck	HXTP25

Online Resources

eCatalog

