


HUBBELL-PRO LOCKING PLUG

KEY FEATURES:

- Impact modified nylon body construction
- Rubber dust shield
- NEMA configuration and rating marked on device face
- Ready-to-wire
- Clearly marked terminal identification



DIMENSIONS

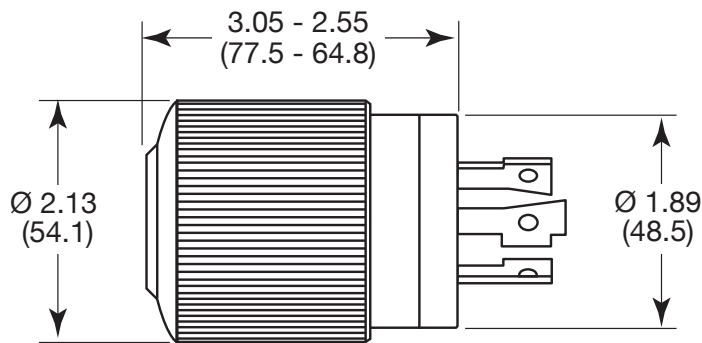

LISTINGS

- UL Standard 498
- CSA Standard C22.2 No. 42-M1984
- CSA Standard C22.2 No. 182.2-M1987
- Fed Spec WC596
- RoHS Compliant

CORD RANGE

- 5 Conductor (stranded copper wire only)
- #14/5 SO - #8/5 SO
.625 in. - 1.050 in. (15.9 mm - 26.7 mm)

PERFORMANCE

- Flammability: V-0
- Operating Temperature:
 - Max. continuous 60°C;
 - Min. -40°C without impact

ENVIRONMENTAL

- NEMA Type 1
- IP20

MATERIALS

Part	Description
Pull Down Ring	Nylon, black
Grip Body	Nylon, black
Terminal Cover	Lexan
Drive Screw	Steel, Zinc Plate
Dust Shield	Rubber
Assembly Screw	Steel, Zinc Plate
Terminal Screw	Steel, Green, Nickel, Brass
Wire Clamp Nut	Brass/Steel/Tin Plate
Blades	Brass
Plug face	Nylon, White

ACCESSORIES

- Weather protective boot **HBP2**

NEMA No.	Config.	Rating	Pole/Wire	Catalog Number
L21-20P		20A 3ØY 120/208V AC	4P 5W Grounding	L2120P
L21-20P		20A 3ØY 120/208V AC	4P 5W Grounding	L2120PM1 (Bulk Pack - 100 pcs)
L22-20P		20A 3ØY 277/480V AC	4P 5W Grounding	L2220P
L23-20P		20A 3ØY 347/600V AC	4P 5W Grounding	L2320P
L21-30P		30A 3ØY 120/208V AC	4P 5W Grounding	L2130P
L22-30P		30A 3ØY 277/480V AC	4P 5W Grounding	L2230P
L23-30P		30A 3ØY 347/600V AC	4P 5W Grounding	L2330P