


HUBBELL-PRO LOCKING PLUG

KEY FEATURES:

- Impact modified nylon body construction
- Rubber dust shield
- NEMA configuration and rating marked on device face
- Ready-to-wire
- Clearly marked terminal identification



DIMENSIONS

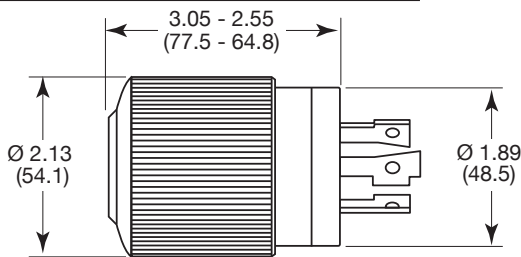

NEMA No.	Config.	Rating	Pole/Wire	Catalog Number
L5-20P		20A 125V	2P 3W Grounding	L520P
L6-20P		20A 250V	2P 3W Grounding	L620P
L7-20P		20A 277V AC	2P 3W Grounding	L720P
L8-20P		20A 480V AC	2P 3W Grounding	L820P
L5-30P		30A 125V	2P 3W Grounding	L530P
L6-30P		30A 250V	2P 3W Grounding	L630P L630PM2* <small>Bulk Pack 100 pcs</small> L630PBKM2* <small>All Black, Bulk Pack 100 pcs</small>
L7-30P		30A 277V AC	2P 3W Grounding	L730P
L8-30P		30A 480V AC	2P 3W Grounding	L830P

LISTINGS

- UL Standard 498
- CSA Standard C22.2 No. 42-M1984
- CSA Standard C22.2 No. 182.2-M1987
- PSE (L620P, L630P, L630PM2, L630PBKM2)
- Fed Spec WC596 (except **L630P, L820P, L830P**)
- RoHS Compliant

CORD RANGE

- 3 Conductor (stranded copper wire only)
- #18/3 SJ - #8/3 SO
 - .300 in. - .950 in. (7.6 mm - 24.1 mm)
- *Recommended for use with .500 in.-.950 in. cable

PERFORMANCE

- Flammability: V-0
- Operating Temperature:
 - Max. continuous 60°C;
 - Min. -40°C without impact

ENVIRONMENTAL

- NEMA Type 1
- IP20

MATERIALS

Part	Description
Pull Down Ring	Nylon, black
Grip Body	Nylon, black
Terminal Cover	Lexan
Drive Screw	Steel, Zinc Plate
Dust Shield	Rubber
Assembly Screw	Steel, Zinc Plate
Terminal Screw	Steel, Green, Nickel, Brass
Wire Clamp Nut	Brass/Steel/Tin Plate
Blades	Brass
Plug face	Nylon, White

ACCESSORIES

- Weather protective boot **HBP2**