


HUBBELL-PRO 15A & 20A STRAIGHT BLADE CONNECTORS AND 15A LOCKING CONNECTORS

**KEY FEATURES:**

- Impact modified nylon body construction
- Rubber dust shield
- NEMA configuration and rating marked on device face
- Ready-to-wire
- Clearly marked terminal identification



**DIMENSIONS**

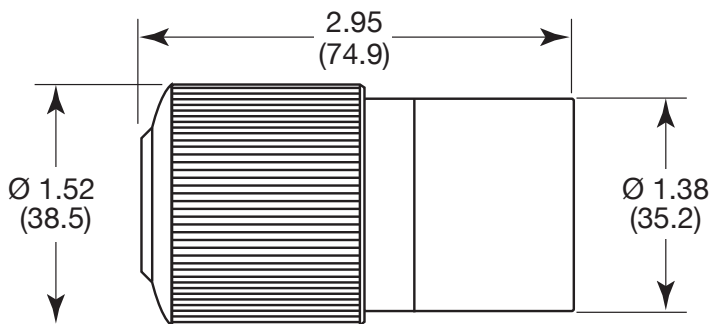

**LISTINGS**

- UL Standard 498
- CSA Standard C22.2 No. 42-M1984
- CSA Standard C22.2 No. 182.2-M1987
- Fed Spec WC596
- RoHS Compliant

**CORD RANGE**

- 3 Conductor (stranded copper wire only)
- #18/3 SJ - #12/3 SO
  - .300 in. - .655 in. (7.6 mm - 16.6 mm)

**PERFORMANCE**

- Flammability: V-0
- Operating Temperature:
  - Max. continuous 60°C;
  - Min. -40°C without impact

**ENVIRONMENTAL**

- NEMA Type 1
- IP20

**MATERIALS**

Part	Description
Pull Down Ring	Nylon, black
Grip Body	Nylon, black
Terminal Cover	Lexan
Drive Screw	Steel, Zinc Plate
Dust Shield	Rubber
Assembly Screw	Steel, Zinc Plate
Terminal Screw	Steel, Green, Nickel, Brass
Wire Clamp Nut	Brass/Steel/Tin Plate
Contacts	Brass
Connector face	Nylon, White

**ACCESSORIES**

- Weather protective boot **HBC1**

NEMA No.	Config.	Rating	Pole/Wire	Catalog Number
5-15R		15A 125V	2P 3W Grounding	<b>515SC</b>
5-20R		20A 125V	2P 3W Grounding	<b>520SC</b>
L5-15R		15A 125V	2P 3W Grounding	<b>L515C</b>
L7-15R		15A 277V AC	2P 3W Grounding	<b>L715C</b>