

Accessories

OPTIMYZER[®]

Low Bay Replacement Lens

Features

- 180° Lens for low bay applications
- 3 to 1 radius-to-mounting height, 8' to 16' sensor mounting height
- IP65, NEMA 3R watertight, and outdoor rated, when use with suffix XT sensors

Ordering Information

Description	Device Color	UPC Number	Catalog Number
180° Lens for low bay applications	White	783585565187	LBRLXT180

Listings

cULus Listed

Specifications


Casing	High-impact injection-molded thermoplastic
Size	3.25" Diameter x 1.25 height
Weight	0.8 oz
Mounting	Insert and twist clockwise on sensor's face

Performance

Environment

Moisture Resistance	IP65 Suitability
Operating temperature	-40°F to 149°F (-40°C to 65°C)
Relative humidity	0% to 95%

HUBBELL

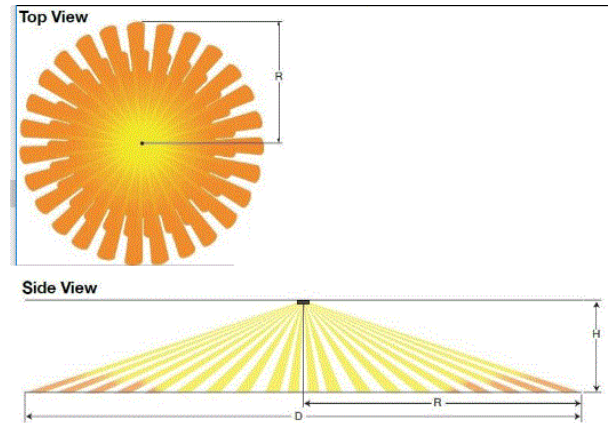

Online Resources

eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

