

Features

- 360° Lens for low bay applications
- 3 to 1 radius-to-mounting height, 8' to 16' sensor mounting height
- IP65, NEMA 3R watertight, and outdoor rated, when use with suffix XT sensors

Ordering Information

Description	Device Color	UPC Number	Catalog Number
360° Lens for low bay applications	White	783585565194	LBRLXT360

Listings

cULus Listed


Specifications

Casing	High-impact injection-molded thermoplastic
Size	3.25" Diameter x 1.25 height
Weight	0.8 oz
Mounting	Insert and twist clockwise on sensor's face

Performance

Environment

Moisture Resistance	IP65 Suitability
Operating temperature	-40°F to 149°F (-40°C to 65°C)
Relative humidity	0% to 95%

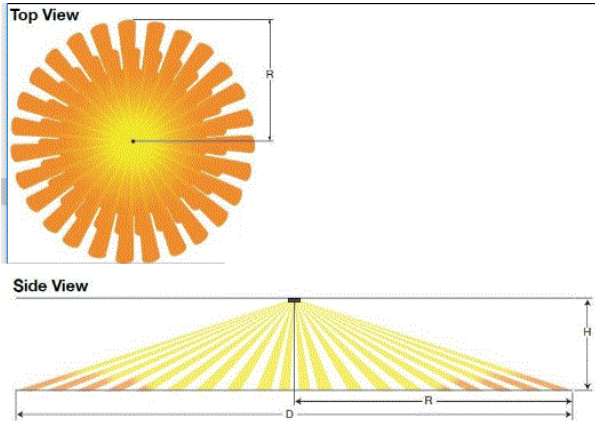

Online Resources

eCatalog