

Load:Logic®

Room Controller

2-Relay, 0-10V Dimming

HUBBELL

Features

- Self contained intelligent device that provides standalone room level control
- Energy efficient advanced device auto configuration
- ON/OFF, Dimming and Zone Control, Daylight Harvesting
- Plenum rated

Ordering Information

Description	Device Color	UPC Number	Catalog Number
2 - Relay, Two 0-10V Dimming Channels Room Controller	Yellow	783585564135	LLC2RD



Listings

UL916, ASHRAE 90.1, IEEC, California Title 24 (CEC), cUL, LEED Compliant

Specifications

Body	UL rated 94HB plastic
Dimensions	1.30" H x 3.85" W x 5.75" L


Performance

Electrical

Current Sinking Capacity	60mA per channel
Input (Single feed)	120/277/347V AC
Output	20A, Tungsten, Ballast, 8A LED, 1hp @ 120V, 3/4hp @ 277V AC

Environmental

Operating Location	Indoor Use Only
Operating Temperature	0° to 40°C (32° to 104°F) Relative Humidity (non-condensing) 0% to 95%

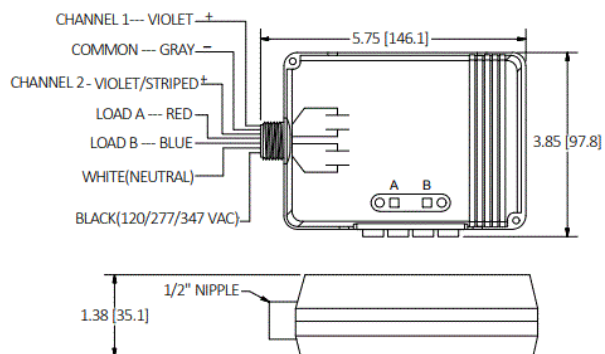

Complementary Products

Configuration Device	RCBTM
Patch cord	NSC5EY10PNB

Online Resources

Customer Use Drawing
eCatalog
Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

