

TradeSelect®  
**Single Pole, 15A 120V AC**  
**Switches and Lighting Controls**  
**2 Single Pole Toggles**

**HUBBELL®**

**Features**

- Quiet snap action mechanism
- Self-grounding staple is standard
- Elongated strap with continuous plaster ears

**Ordering Information**

Description	UPC	Catalog Number
TradeSelect, Combination, Grounding, Push and Side Wire, 15A 120V AC, 2 Single Pole Toggles, White	883778109799	RC101W

**Listings**

CSA Certified  
 UL Listed E3896

**Specifications**


Color	White nylon
Contact Configuration	Two Position
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Traditional Switch Combo Devices
Mounting Hardware	Mounting Screws
Number Of Poles	2- Single Pole

**Performance**

Operating Cycles	30,000 Minimum
Operating Temperature	Max Continuous- 60 Degrees C, Minimum- -20 Without Impact
Performance	Environmental - Operating temperature - -20°C to 60°C

**Electrical**

Amperage Rating	15 A
Connectivity	Side Wired
Contact Rating	15A
Current / Amperage Rating	15 A
Current Rating	15 A
Voltage Rating	120 VAC
Voltage Rating Description	120 VAC
Wattage	1800

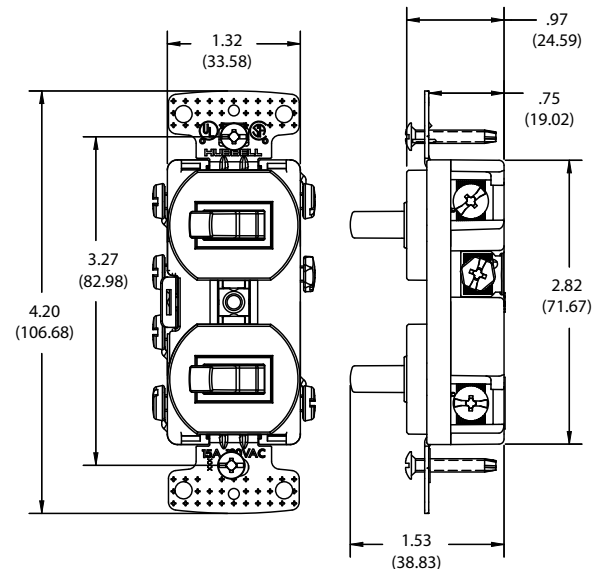

**Links**

- [Customer Drawings](#)
- [Installation Instructions](#)
- [Media](#)

